



HONSEL

The Art of **Fastening**

90
YEARS
1930-2020



Proven quality
in a new design.



Manual riveting tools

BZ 2

Hand tool for blind rivets
> with opening spring



**Good ergonomics,
brilliant transformation**



BZ 2A NEW !
with mandrel container



Delivery in blister packs

BZ 44

Hand tool for blind rivets
> with opening spring



**The classic tool –
sturdy and reliable**



**With holding mechanism for the
mandrel.**

The mandrel is held in the tool before and after the riveting process, so that the tool can be easily operated with one hand, while the other hand can hold the workpiece.



Delivery in blister packs

BZ 2

Weight 0.56 kg
Stroke 8 mm
Packaging Blister
Content 4 Nosepieces



Blind rivets 

	2.4	3.0	3.2	4.0	4.8	5.0	6.0	6.4	8.0	
Aluminium	■									
Steel	■									
Stainless steel	■									
Copper alloys	■									

Also available with assortment



BZ 44

Weight 0.63 kg
Stroke 9.5 mm
Packaging Blister
Content 4 Nosepieces



Blind rivets 

	2.4	3.0	3.2	4.0	4.8	5.0	6.0	6.4	8.0	
Aluminium	■									
Steel	■									
Stainless steel	■									
Copper alloys	■									

Also available with assortment




BZ 70/72

Lever tool for blind rivets



Sturdy construction. Reliable setting of blind rivets even with large diameters.

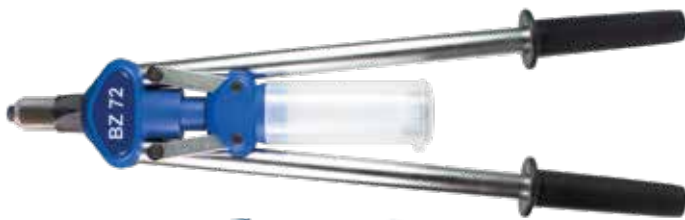

Replacement nose pieces in closed compartment on the mandrel collector.




Lever tool BZ 70 in impact-resistant plastic case

BZ 58

Shear blind riveting tool



Simple operation, very good power transmission.

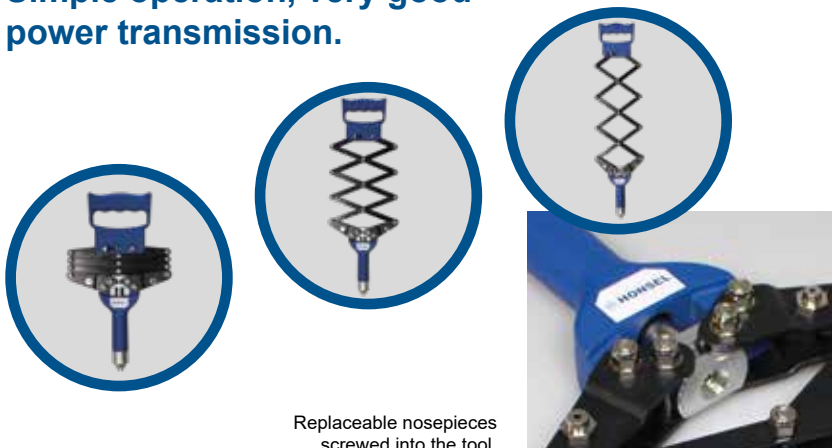

Replaceable nosepieces screwed into the tool.

BZ 70

Weight 1.5 kg
Stroke 14.5 mm
Packaging Plastic case
Content 4 Nosepieces
max. mandrel- \varnothing 3.2 mm



Blind rivets

	2.4	3.0	3.2	4.0	4.8	5.0	6.0	6.4	8.0
Aluminium									
Steel									
Stainless steel									
Copper alloys									

BZ 72

Weight 1.65 kg
Stroke 14.5 mm
Packaging Plastic case
Content 4 Nosepieces
max. mandrel- \varnothing 4.0 mm

Blind rivets

	2.4	3.0	3.2	4.0	4.8	5.0	6.0	6.4	8.0
Aluminium									
Steel									
Stainless steel									
Copper alloys									

BZ 58

Weight 2.0 kg
Stroke 11 mm
Packaging Carton
Content 4 Nosepieces
max. mandrel- \varnothing 3.8 mm



Blindniete

	2.4	3.0	3.2	4.0	4.8	5.0	6.0	6.4	8.0
Aluminium									
Steel									
Stainless steel									
Copper alloys									



VNG 255

Hand tool for blind rivet nuts and blind rivet studs

- > Including product assortment
- > 360° rotating head

The best-seller - sold over 10,000 times!




Practically unlimited working positions



Universal and flexible in use!

VNG 371

Hand tool for blind rivet nuts and blind rivet studs

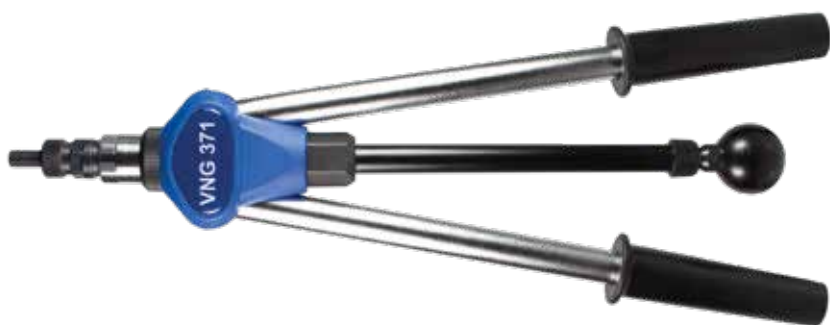

Easy unscrewing thanks to threaded rod



Quick-change system for the threaded mandrel.



Delivery in impact-resistant plastic case

BZ 70

Weight 0.9 kg
Packaging Plastic case

Blind rivet nuts

	M3	M4	M5	M6	M8	M10	M12
optional	Aluminium						
optional	Steel						
optional	Stainless steel						

Blind rivet studs

	M3	M4	M5	M6	M8	M10	M12
	Steel						

With assortment



VNG 371

Weight 1.2 kg
Packaging Plastic case

Content

- each with 1 piece conversation kit for blind rivet nuts M5, M6, M8, M10
- each with 1 piece threaded sleeve for blind rivet bolts M5, M6, M8

Blind rivet nuts

	M3	M4	M5	M6	M8	M10	M12
	Aluminium						
	Steel						
	Stainless steel						

Blind rivet studs

	M3	M4	M5	M6	M8	M10	M12
	Steel						



VNG 152

Hand tool for blind rivet nuts and blind rivet studs
> with hydraulics



Hydraulically assisted setting without great effort.



VNG 612

Hand tool for blind rivet nuts and blind rivet studs



Newly optimised version!

Smooth ratchet mechanism for blind rivet nuts up to M12



VNG 152

Weight 0.6 kg
Packaging Plastic case

Content

- each with 1 piece conversation kit for blind rivet nuts M3-M8
- each with 1 piece conversation kit for blind rivet studs M4-M8

Blind rivet nuts

M3	M4	M5	M6	M8	M10	M12
Aluminium						
Steel						
Stainless steel						

Blind rivet studs

M3	M4	M5	M6	M8	M10	M12
Steel						



VNG 152

Weight 1.1 kg
Packaging Case in alluminium look

Content

- each with 1 piece conversation kit for blind rivet nuts M5-M12
- each with 1 piece threaded sleeve for blind rivet studs M5- M8

Blind rivet nuts

M3	M4	M5	M6	M8	M10	M12
* Aluminium						
* Steel						
* Stainless steel						

* optional

Blind rivet studs

M3	M4	M5	M6	M8	M10	M12
Steel						



MULTI 1

Hand tool for blind rivets, blind rivet nuts and blind rivet studs

> 360° rotating head



Steplessly pivotable through 360°


MULTI 1 in impact-resistant plastic case



MULTI 5

Lever Tool for blind rivets, blind rivet nuts and blind rivet studs

> fold-away arms

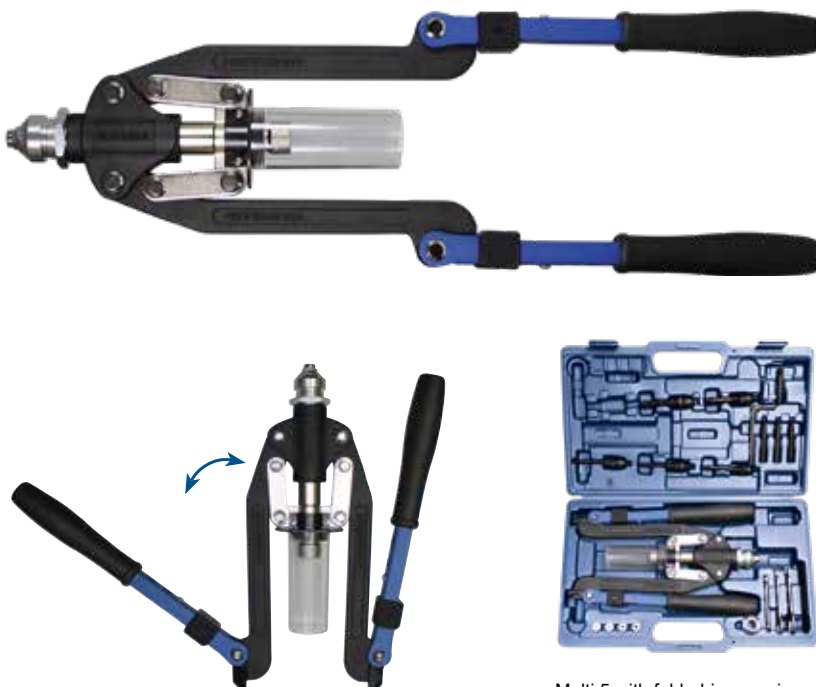

Multi 5 with folded-in arms in impact-resistant plastic case.

MULTI 1

Weight: 0.56 kg
Packaging: Plastic case

Content:

- each with 1 nose piece for blind rivets 2.4; 3.0/3.2mm; 4.0 mm; 4.8/5.0mm
- each with 1 piece conversation kit for blind rivet nuts M3-M6
- each with 1 piece threaded sleeve for blind rivet studs M4-M6
- each with 1 piece jaw wrench AF 17/19, AF 21/27, AF 5/8

Blind rivets

2.4	3.0	3.2	4.0	4.8	5.0	6.0
Aluminium						
Steel						
Stainless steel						
Copper alloys						

Blind rivet nuts

M3	M4	M5	M6	M8	M10	M12
Aluminium						
Steel						

Blind rivet studs

M3	M4	M5	M6	M8	M10	M12
Steel						

MULTI 5

Weight: 1,9 kg
Packaging: plastic case

Content:

- each with 1 nosepiece for blind rivets 3.0/3.2mm; 4.0mm; 4.8/5.0mm; 6.0mm; 6.4mm
- each with 1 piece conversation kit for blind rivet nuts M4-M10
- each with 1 piece threaded sleeve for blind rivet studs M4-M8

Blind rivets

3.0	3.2	4.0	4.8	5.0	6.0	6.4
Aluminium						
Steel						
Stainless steel						
Copper alloys						

Blind rivet nuts

M3	M4	M5	M6	M8	M10	M12
Aluminium						
Steel						

Blind rivet studs

M3	M4	M5	M6	M8	M10	M12
Steel						

BZ2 Assortment



BZ 2 with OPTO® aluminium/steel fasteners

Product box of sturdy plastic with BZ 2 blind riveter incl. jaw wrench, additional clamping jaws, 1 drill each 3.3 mm, 4.1 mm and 4.9 mm and 300 blind rivets.

BZ44 Assortment



BZ 44 with ALFO® aluminium/steel fasteners

Product box of sturdy plastic with BZ 44 blind riveter incl. jaw wrench, additional clamping jaws, 1 drill each 3.1 mm and 4.1 mm and 350 blind rivets.

VNG255 Assortment



VNG 255 in assortment box

Product box of sturdy plastic with VNG 255 for blind rivet nuts and blind rivet studs, incl. 1x conversion kit each for M4/M5/M6 blind rivet nuts, 1x threaded sleeve each for RIFBOLT® M4/M5 blind rivet studs, 1x open-jaw wrench each for A/F 22 and A/F 24 and SW 6 Allen key.

Compact assortment boxes in sturdy plastic cases!

HONSEL



Blind rivets



Blind rivet nuts



Blind rivet studs



HONSELcoils



Self-clinching elements



Powertrain fasteners



Bolts and sleeves



Special parts



Manual riveters



Pneumatic riveters



Battery riveters



Automation components



Process monitoring

Honsel Distribution GmbH & Co.
Friedrich-Wöhler-Str.44
24536 Neumünster
Deutschland

fon ++49 4321 - 96 71 71
fax ++49 4321 - 96 71 96
mail info@honsel.de

825.100.200.060-1-1